


RTD's

1/4" DIAMETER, 10" LONG RTD PROBE WITH TWO-WIRE MONO PHONE PLUG TERMINATION

- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 10"
- TERMINATION — TWO-WIRE MONO PHONE PLUG

OSK70420
\$115 each
 Plus One-Time Set-Up Charge

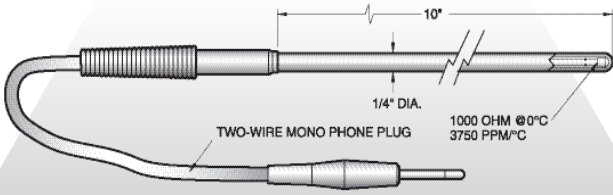

1/16" DIAMETER PR-11 RTD PROBE WITH 18" OF EXIT-3CU-26S-SB

- SHEATH DIA. — 1/16"
- SHEATH LENGTH — 6"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 18"
- WIRE INSULATION — PFA WITH STAINLESS STEEL OVERBRAID
- TERMINATION — TA3F CONNECTOR

OSK70313
\$149 each
 Plus One-Time Set-Up Charge



4-WIRE, 1/16" DIAMETER PR-11 RTD PROBE

- SHEATH MATERIAL — 304 STAINLESS STEEL
- SHEATH DIA. — 1/16"
- WIRE AWG — 26 STRANDED
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS
- SPECIAL OPTIONS — SPADE LUG AND DTC TERMINATIONS AVAILABLE

OSK70359
\$123 each
 Plus One-Time Set-Up Charge



SOME TERMINATION OPTIONS:


SPADE LUGS SPECIFY "LUG"

DUAL CONNECTOR SPECIFY "DTC"

RTD PROBE WITH SHRINK TUBING FOR INCREASED MOISTURE RESISTANCE

- SHEATH LENGTH — 6"
- WIRE LENGTH — 120"
- TERMINATION — STRIPPED LEADS


OSK70103
\$120 each
 Plus One-Time Set-Up Charge

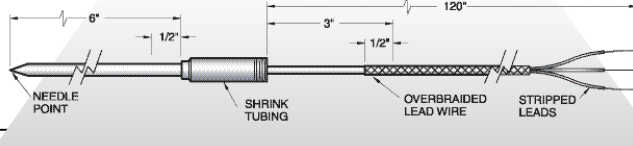

PR-11 STYLE RTD PROBE WITH THIN FILM ELEMENT AND ALUMINUM SHEATH

- SHEATH MATERIAL — ALUMINUM
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 9"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS


OSK60794
\$145 each
 Plus One-Time Set-Up Charge

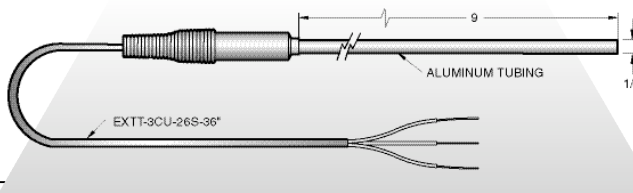

CUSTOM RTD PROBE WITH FLANGE

- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 13.25"
- WIRE LENGTH — 8"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

OSK70351
\$157 each
 Plus One-Time Set-Up Charge

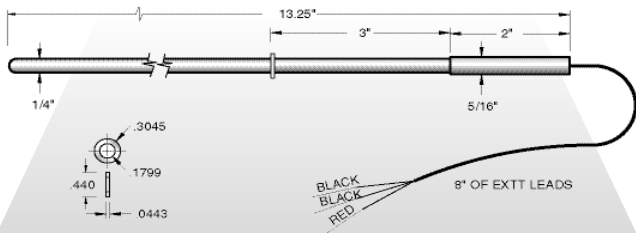

DUAL PR-11 WITH DBL BEND AND BX CABLE

- TERMINATION — STRIPPED LEADS


OSK60280
\$182 each
 Plus One-Time Set-Up Charge



DUAL PR-11 IN 1/4" DIAMETER HASTELLOY C SHEATH

- SHEATH MATERIAL — HASTELLOY C
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 7"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

OSK60855
\$218 each
 Plus One-Time Set-Up Charge

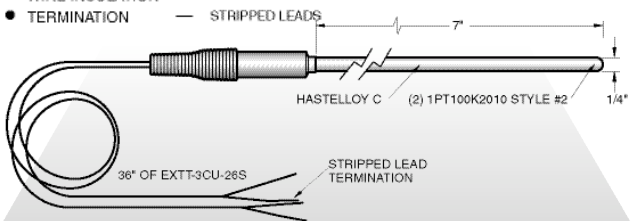

DUAL PR-11 WITH BEND AND BX CABLE

- TERMINATION — SPADE LUGS

OSK5092B
\$239 each
 Plus One-Time Set-Up Charge




RTD's (cont'd)

DUAL RTD PROBE WITH BEND AND OVERBRAIDED WIRE

- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 3", 1-5/8" BEND AT 90°
- WIRE LENGTH — 36"
- WIRE AWG — 22
- WIRE INSULATION — STAINLESS STEEL OVERBRAID
- TERMINATION — STRIPPED LEADS


OSK50087
\$135 each
 Plus One-Time Set-Up Charge

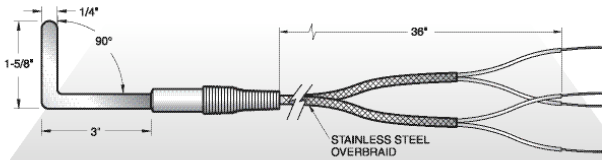

PR-11 PROBE WITH RECTANGULAR CROSS-SECTION SHEATH

- SHEATH MATERIAL — 300 SERIES STAINLESS STEEL
- SHEATH DIA. — .188 X .250
- SHEATH LENGTH — 1.500"
- WIRE AWG — 22
- WIRE INSULATION — GLASS WITH STAINLESS STEEL OVERBRAIDING
- TERMINATION — STRIPPED LEADS

 
OSK4068
\$100 each
 Plus One-Time Set-Up Charge



DUAL PR-11-2-100-1/8-9-E WITH 60' LEADS ONE SET OF LEADS ASSEMBLED TO SUB D CONNECTOR THE OTHER SET - STRIPPED LEADS

- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 9"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 60"
- WIRE INSULATION — PFA
- TERMINATION — SUB D CONNECTOR, STRIPPED LEADS

 
OSK4605
\$170 each
 Plus One-Time Set-Up Charge



1/16" DIA., 36" RTD PROBE WITH GLASS BRAID INSULATION

- SHEATH MATERIAL — INCONEL 600
- SHEATH DIA. — 1/16"
- SHEATH LENGTH — 6"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 36"
- WIRE INSULATION — GLASS BRAID
- TERMINATION — STRIPPED LEADS

 
OSK3703
\$140 each
 Plus One-Time Set-Up Charge



RTD PROBE WITH 3/8" DIAMETER FLANGE AND BLACK SHRINK TUBING

- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 20"
- WIRE AWG — 20
- WIRE LENGTH — 6"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS


OSK3735
\$146 each
 Plus One-Time Set-Up Charge

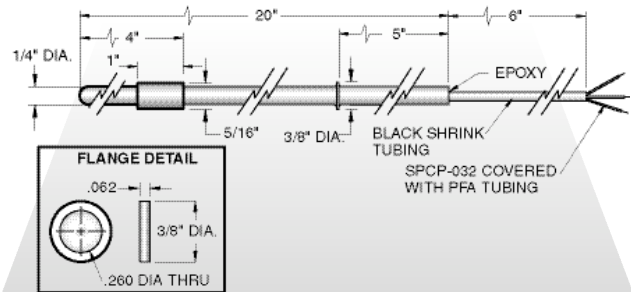

1/16" DIAMETER STYLE 3 RTD PROBE WITH SMP-U-M CONNECTORS, 1 BLACK, 1 RED WIRE EACH CONNECTOR

- SHEATH DIA. — 1/16"
- SHEATH LENGTH — 2"
- WIRE LENGTH — 36"
- TERMINATION — SMP-U-M


OSK4551
\$127 each
 Plus One-Time Set-Up Charge

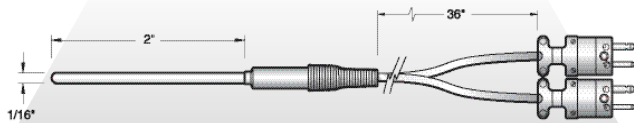

PR-11 STYLE RTD PROBE WITH 45 DEGREE BEND AND SB LEAD WIRE

- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 2", 2" BEND AT 135°
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 36"
- WIRE INSULATION — GLASS WITH STAINLESS STEEL OVERBRAID
- TERMINATION — OTP


OSK4116
\$93 each
 Plus One-Time Set-Up Charge

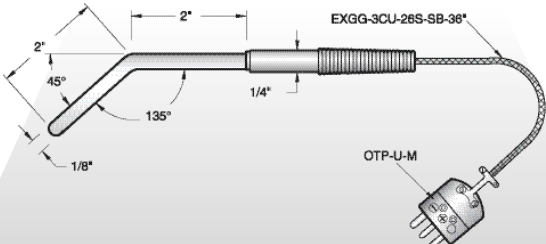

1/16" DIAMETER, 5" LONG RTD PROBE WITH 72" FIBERGLASS INSULATED EXTENSION WIRES

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/16"
- SHEATH LENGTH — 5"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 72"
- WIRE INSULATION — FIBERGLASS
- TERMINATION — STRIPPED LEADS


OSK3490
\$134 each
 Plus One-Time Set-Up Charge

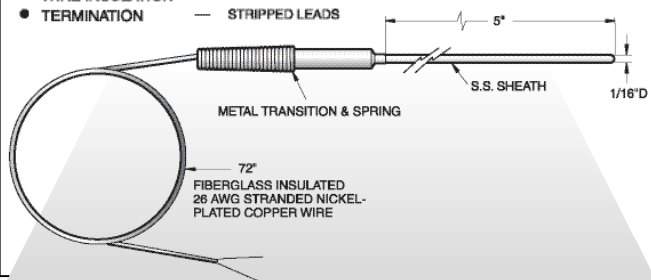

3/16" DIAMETER RTD PROBE WITH SSLK-316-18 COMPRESSION FITTING

- SHEATH DIA. — 3/16"
- SHEATH LENGTH — 1/2"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 5 FT.
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS


OSK2092
\$88 each
 Plus One-Time Set-Up Charge

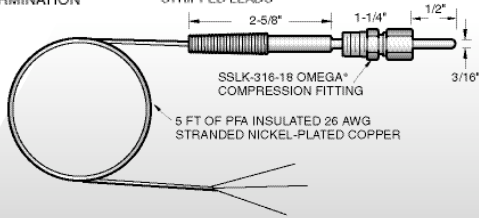

1/16" DIAMETER PR-11 RTD WITH OMEGA CLAD® EXTENSION AND LEAD WIRE

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/16" RIGID, .040" FLEXIBLE
- SHEATH LENGTH — 6.625" RIGID, 18" FLEXIBLE
- WIRE LENGTH — 72"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS

OSK1692
\$126 each
 Plus One-Time Set-Up Charge

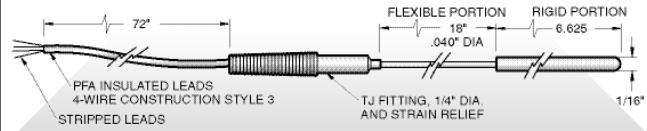


X

1/4" RTD PROBE AND TC WITH TRANSITION JUNCTION

- SHEATH MATERIAL — 304 STAINLESS STEEL
- SHEATH DIA. — 1/4"
- WIRE AWG — 26 AND 24 STRANDED
- WIRE LENGTH — 20 FT. OF EACH
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS


OSK2048
\$201 each
 Plus One-Time Set-Up Charge

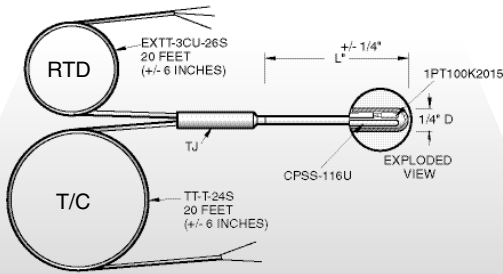

6 MM DIAMETER RTD PROBE WITH 3M BX CABLE

- SHEATH MATERIAL — 316 STAINLESS STEEL
- SHEATH DIA. — 6 MM
- SHEATH LENGTH — 75 MM (3")
- WIRE LENGTH — 3 M
- TERMINATION — STRIPPED LEADS

 
OSK2039
\$158 each
 Plus One-Time Set-Up Charge



4-WIRE PR-11 STYLE STD, WITH DISK

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/16"
- SHEATH LENGTH — 5.125"
- TERMINATION — STRIPPED LEADS

 
OSK1576
\$248 each
 Plus One-Time Set-Up Charge



RTD PROBE FOR USE IN 100% HUMIDITY

- SHEATH MATERIAL — 316 STAINLESS STEEL
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 125"
- WIRE AWG — 26 STRANDED
- WIRE INSULATION — PFA
- TERMINATION — LEMO CONNECTOR


OSK2148
\$171 each
 Plus One-Time Set-Up Charge

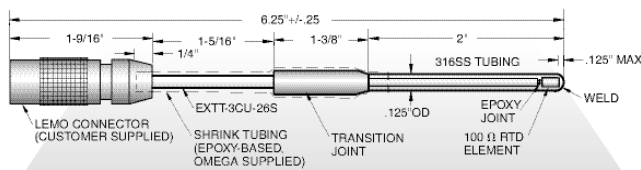

RTD PROBE WITH HASTELLOY SHEATH AND OTP CONNECTOR TERMINATION

- SHEATH MATERIAL — HASTELLOY C
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 12"
- WIRE AWG — 26 STRANDED
- WIRE LENGTH — 48"
- WIRE INSULATION — PFA
- TERMINATION — OTP


OSK1226A
\$154 each
 Plus One-Time Set-Up Charge

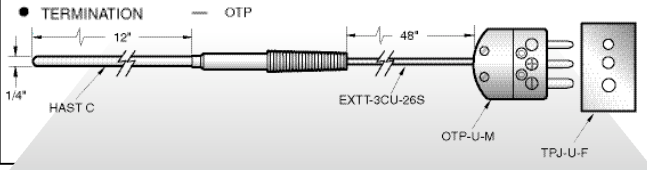

PR-11 RTD PROBE WITH PENETRATION TIP AND 13 FT. UNCOILED RSC CABLE

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 9"
- TERMINATION — STRIPPED LEADS

 
OSK1691
\$169 each
 Plus One-Time Set-Up Charge



RIGHT ANGLE RTD PROBE WITH 304 STAINLESS STEEL THICK WALL TUBING AND GLASS INSULATED WIRES

OSK0508
\$82 each
 Plus One-Time Set-Up Charge

- SHEATH MATERIAL — 304 STAINLESS STEEL
- SHEATH DIA. — 1/8"
- SHEATH LENGTH — 1", 6-1/4" BEND AT 90°
- WIRE AWG — 26 STRANDED
- WIRE INSULATION — GLASS BRAID
- TERMINATION — STRIPPED LEADS

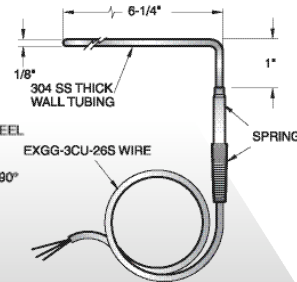


RTD's (cont'd)

STYLE 3 RTD WITH 2 PAIRS OF WIRES SIDE BY SIDE RATHER THAN STACKED

- WIRE AWG — 20
- WIRE INSULATION — GLASS OVER GLASS
- TERMINATION — STRIPPED LEADS, RTD ELEMENT


OSK70186
\$65 each
 Plus One-Time Set-Up Charge

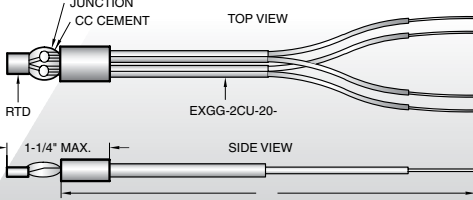

WATER TIGHT ENCAPSULATING OVER RTD ELEMENT ON POLYVINYL INSULATED WIRE

- WIRE AWG — 24
- WIRE LENGTH — 120"
- WIRE INSULATION — POLYVINYL
- TERMINATION — RTD ELEMENT, TA3F


OSK3224
\$85 each
 Plus One-Time Set-Up Charge

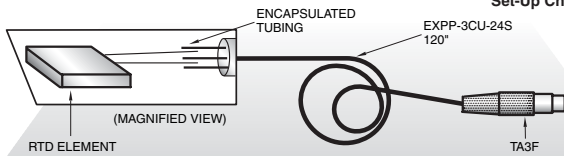

RTD ELEMENT ON 9" OF PFA TUBING

- WIRE AWG — 30
- WIRE LENGTH — 9"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS, RTD ELEMENT

 
OSK70667
\$49 each
 Plus One-Time Set-Up Charge



CLOSED END STAINLESS STEEL TUBE WITH NON-STANDARD LENGTH

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH LENGTH — 4"
- WIRE AWG — 26
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA, PVC
- TERMINATION — STRIPPED LEADS


OSK50075
\$71 each
 Plus One-Time Set-Up Charge

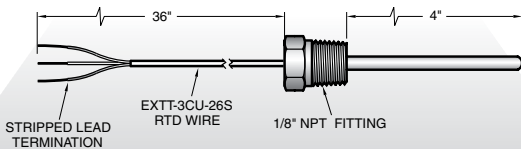

OPEN-END RTD HOUSING WITH 6" OF STAINLESS STEEL TUBING

- SHEATH MATERIAL — STAINLESS STEEL
- SHEATH DIA. — 1/4"
- SHEATH LENGTH — 6"
- WIRE AWG — 26
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS, RTD HOUSING


OSK4438
\$175 each
 Plus One-Time Set-Up Charge

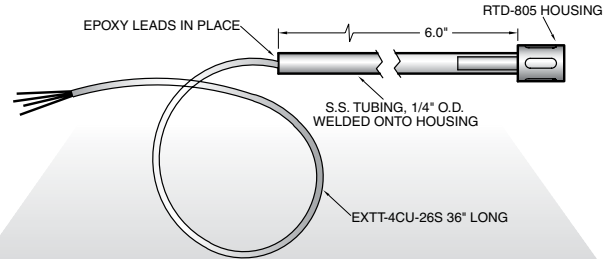

RTD PRECISION PROBE WITH 8' PFA INSULATED LEADS

- WIRE AWG — 26
- WIRE LENGTH — 8'
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS, SCREW-MOUNTED HOUSING


OSK1437
\$295 each
 Plus One-Time Set-Up Charge

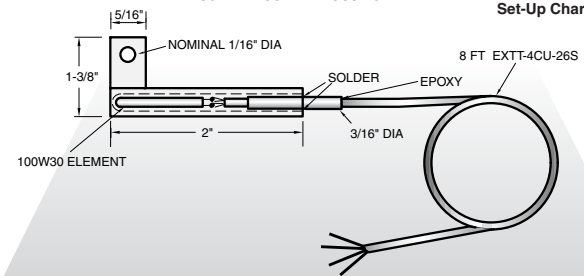

RTD-830 WITH STAINLESS STEEL HOUSING AND 4 FT. ALPHA 7053 LEADS

- WIRE AWG — 26
- WIRE LENGTH — 4'
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS, RTD HOUSING


OSK60372
\$114 each
 Plus One-Time Set-Up Charge

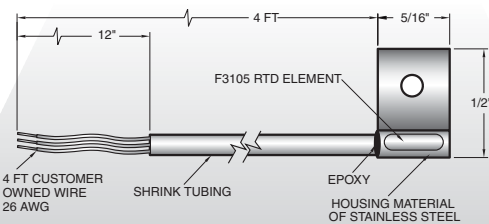

HEX HEAD RTD HOUSING WITH 12" LONG GLASS OVER GLASS INSULATED LEADS

- WIRE LENGTH — 26"
- WIRE INSULATION — GLASS OVER GLASS
- TERMINATION — STRIPPED LEADS, RTD HOUSING


OSK4015
\$147 each
 Plus One-Time Set-Up Charge

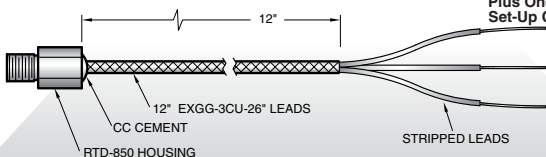

RTD ELEMENT WITH PFA INSULATED 4-CONDUCTOR WIRE

- WIRE AWG — 26
- WIRE LENGTH — 6-1/4"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS, RTD ELEMENT


OSK2221
\$63 each
 Plus One-Time Set-Up Charge

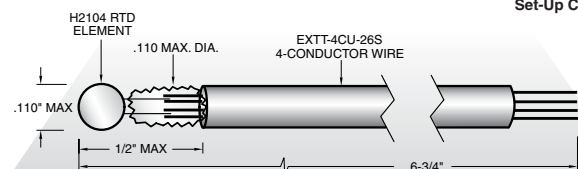

SCREW-MOUNTED ENCAPSULATED SENSOR WITH GLASS OVER GLASS INSULATION

- WIRE AWG — 26
- WIRE LENGTH — 42"
- WIRE INSULATION — GLASS OVER GLASS WITH STAINLESS STEEL OVERBRAID
- TERMINATION — SPADE LUGS, SCREW-MOUNTED RTD HOUSING


OSK3543
\$98 each
 Plus One-Time Set-Up Charge

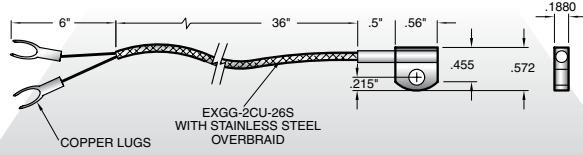

POPULAR PRECISION THERMISTOR WITH BANANA PLUG TERMINATIONS

- TERMINATION — BANANA PLUGS


OSK4149
\$165 each
 Plus One-Time Set-Up Charge

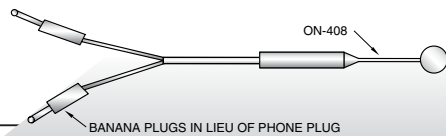

RTD-830 WITH STAINLESS STEEL HOUSING AND 4 FOOT PFA LEADS

- WIRE AWG — 26
- WIRE LENGTH — 4'
- WIRE INSULATION — PFA
- TERMINATION — SCREW-MOUNTED RTD HOUSING


OSK2729
\$114 each
 Plus One-Time Set-Up Charge

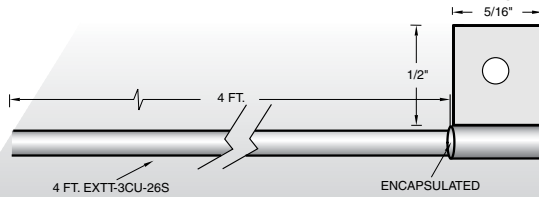

4 LENGTHS OF C.O.M. WIRE WITH RTD ELEMENT

- WIRE LENGTH — 36"
- TERMINATION — STRIPPED LEADS


OSK2383
\$121 each
 Plus One-Time Set-Up Charge

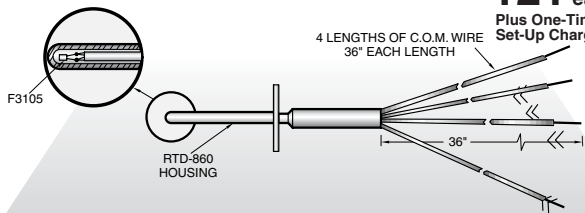

RTD-809 WITH 25 FT LEADS AND BX CABLE

- WIRE LENGTH — 25' 1"
- WIRE INSULATION — PFA
- TERMINATION — MTP MALE CONNECTOR, ENCAPSULATED RTD SENSOR


OSK2183
\$220 each
 Plus One-Time Set-Up Charge

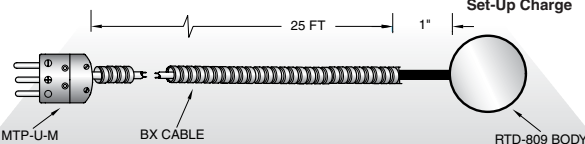

RTD ELEMENT MOUNTED IN OPEN-END HOUSING WITH STAINLESS STEEL FITTING

- SHEATH DIA. — 3/16"
- SHEATH LENGTH — 2"
- WIRE AWG — 26
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS, OPEN-END HOUSING


OSK1641
\$194 each
 Plus One-Time Set-Up Charge

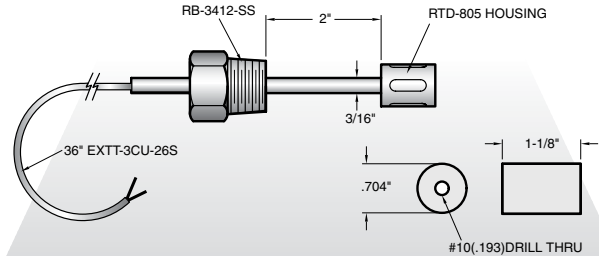

RTD SENSOR WITH TJ BARREL

- SHEATH DIA. — .125
- SHEATH LENGTH — 1.5
- WIRE AWG — 26
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA
- TERMINATION — STRIPPED LEADS


OSK2480
\$135 each
 Plus One-Time Set-Up Charge

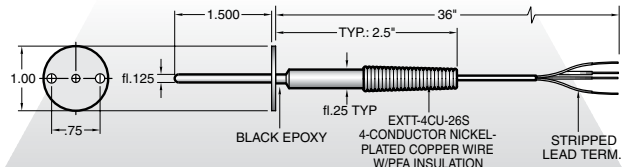


HEX HEAD RTD HOUSING WITH SMTC CONNECTOR AT END

- WIRE AWG — 26
- WIRE LENGTH — 4'
- WIRE INSULATION — PFA
- TERMINATION — SMTC CONNECTOR, RTD HOUSING

OSK4601
\$162 each
 Plus One-Time Set-Up Charge

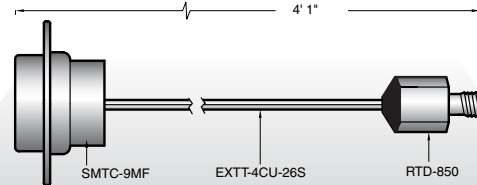

RTD EXTRUDER PROBE WITH SPADE LUG TERMINATION

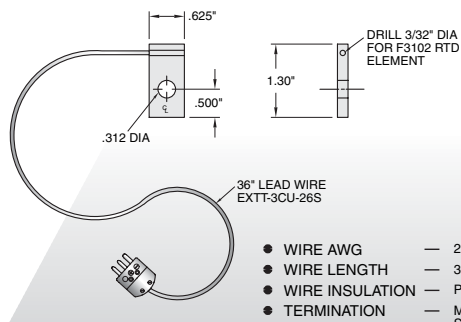


OSK0277
\$109 each
 Plus One-Time Set-Up Charge


- WIRE AWG — 26
- WIRE LENGTH — 36"
- WIRE INSULATION — PFA
- TERMINATION — MTP MALE CONNECTOR, SCREW-MOUNTED HOUSING

RTD's (cont'd)


RTD EXTRUDER PROBE WITH SPADE LUG TERMINATION

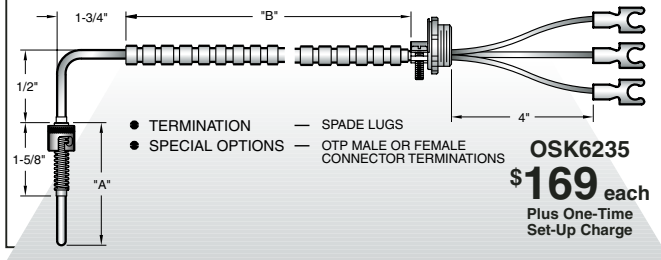


3/16" DIAMETER RTD PROBE WITH NB1-4 PROTECTION HEAD

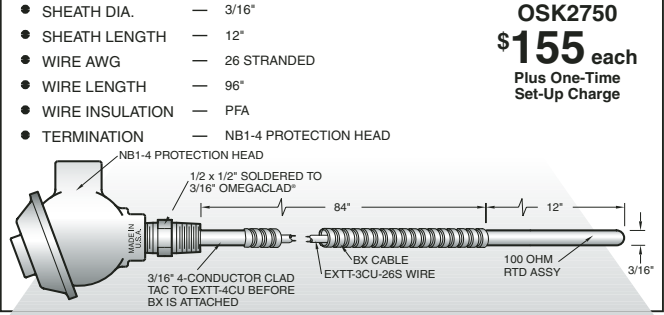


PR-12 STYLE RTD PROBE WITH NEPB HEAD AND THREE ELEMENTS AT TIP

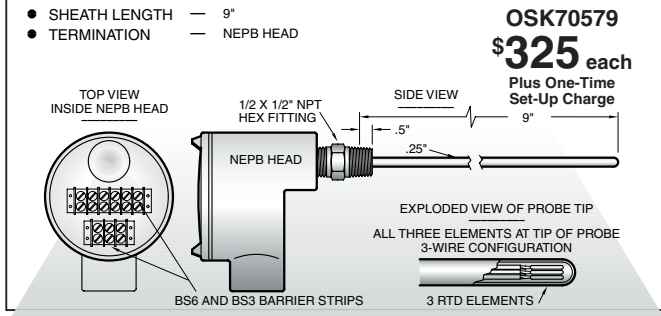


THIN FILM RTD AFFIXED TO CUSTOMER SUPPLIED SUBSTRATE

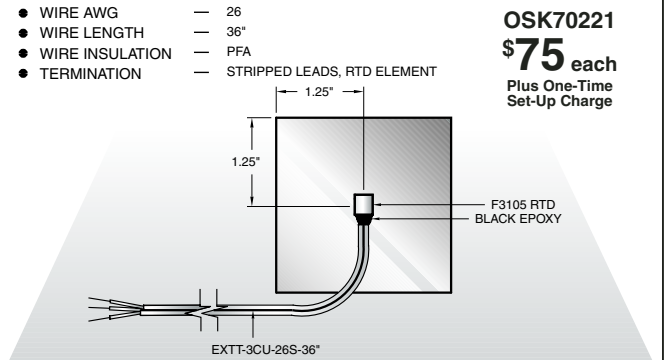


RTD'S ON SILICONE WAFER

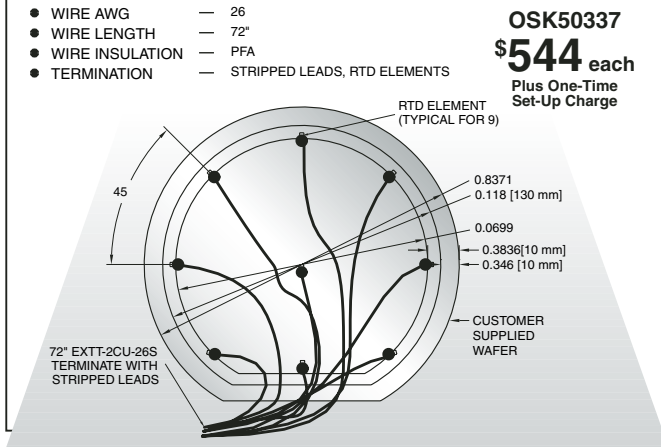

SILICON WAFER WITH RTD'S EPOXIED ON

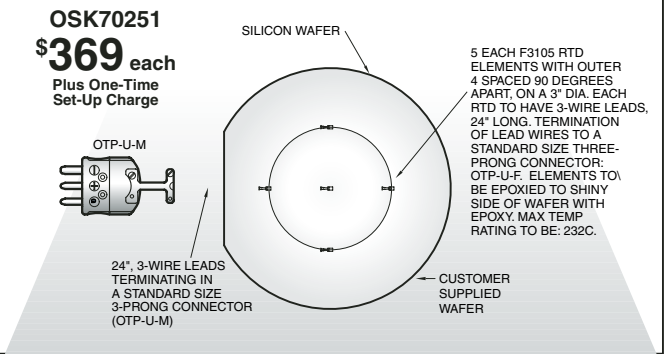

5 POINT RTD WAFER ASSEMBLY

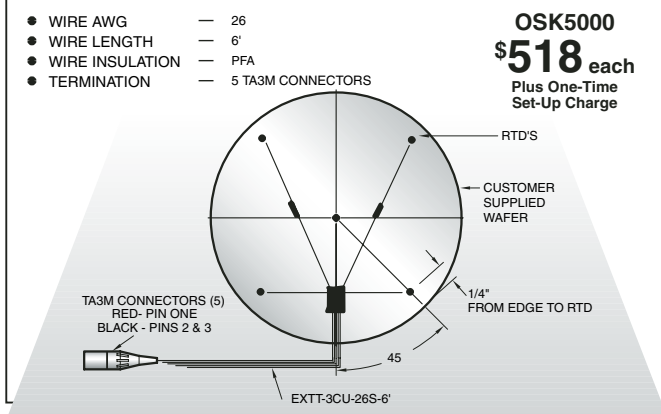

RTD ELEMENT EPOXIED TO MAGNET

